

ロッド型Z-θアクチュエータ、メガトルクモータ™ 薄型PNモータ



省フットプリントな 昇降-回転アクチュエータ

薄型DDモータの ラインナップ拡充




特長

- ✓メガトルクモータ™と
スプライン付きボールねじ
で昇降-回転機構を実現
- ✓自重落下防止用
ブレーキ搭載
- ✓防水構造 (取付部より上側)
ミスト環境下で使用可能



Z-θアクチュエータ

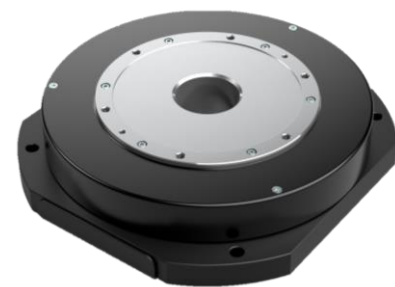

薄型PNモータ (PN2025)



EtherCAT®



ドライバEGC型

特長

- ✓薄型
モータ高さ : 42.5 mm
- ✓高トルク
最大トルク : 25 N・m
- ✓低動摩擦トルク
従来品に対し18%低減

MORE THAN PRECISION

Copyright NSK Ltd. All Rights Reserved.

杆型Z-θ执行器, Megatorque Motor™ PN系列马达 **NSK**

节省空间的升降-旋转执行器

薄型DD马达的产品线扩充




特 长

- ✓ Megatorque Motor™与花键丝杆的组合实现升降和旋转机构的一体化
- ✓ 内置防自重下落刹车
- ✓ 安装面板以上部分可进行防水设计, 可在油雾环境下使用



Z-θ 执行器

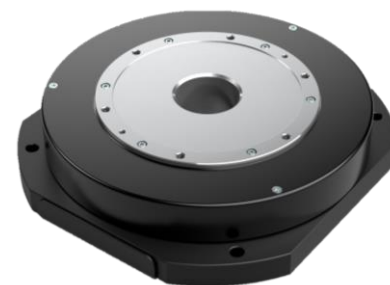

薄型PN马达 (PN2025)



EtherCAT®



EGC型驱动器

特 长

- ✓ 薄型
马达高: 42.5 mm
- ✓ 大扭矩
最大扭矩: 25 N·m
- ✓ 低摩擦转矩
对过完产品降低18%

MORE THAN PRECISION

Copyright NSK Ltd. All Rights Reserved.

Lift-Rotation Z-θ Actuator & Megatorque Motor™ Low-Profile PN Series Direct Drive Motors



Small-footprint lift-and-rotate actuator compatible with an expanded lineup of low-profile direct drive motors



Features

- ✓ A compact solution combining a Megatorque Motor, ball screw, and linear ball spline for vertical and rotary (Z-theta) motion
- ✓ A built-in brake prevents free-fall
- ✓ Waterproof structure (above mounting flange) stands up to mist and spray



Features

- ✓ Low-profile
Motor height: 42.5 mm
- ✓ High torque
Max. torque: 25 N·m
- ✓ Low dynamic torque:
18% lower than conventional products

MORE THAN PRECISION

Copyright NSK Ltd. All Rights Reserved.